




M55229010

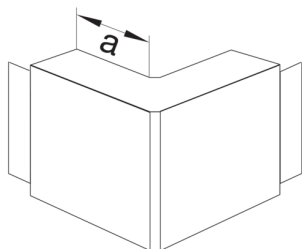

## external corner h-free LFxxx/FB 60x150pw

### Technische Merkmale

#### Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

#### Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

#### Configuration

Antibacterial treatment	no
Symetrical	yes

#### Compatibility

Product compatibility	LF, LFF
-----------------------	---------

#### Connectivity

Trunking coupling	without coupler
-------------------	-----------------

#### Cover, door

Lid with softlip	-
------------------	---

#### Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

#### Dimensions

Trunking height	61 mm
Trunking width	150 mm
Measure a	70 mm

#### Installation, mounting

Base punching	Without base punching
---------------	-----------------------

#### Settings

Angle range	90 °
-------------	------

#### Accessories included

Accessory configuration	Moulded
-------------------------	---------

#### Equipment

With protective film	no
----------------------	----

## Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------

## Safety

Halogen free	yes
Impact strength	IK07

## Use conditions

Operating temperature	-5...90 °C
-----------------------	------------