




LFF600947030

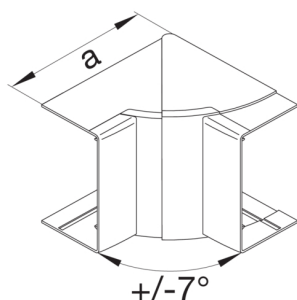

## Adjus. internal corner LFF60090 grey

### Technische Merkmale

#### Architecture

Fixing mode	Clipped
-------------	---------

#### Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

#### Configuration

Antibacterial treatment	no
Symmetrical	yes

#### Connectivity

Trunking coupling	without coupler
-------------------	-----------------

#### Cover, door

Lid with softlip	No
------------------	----

#### Materials

Colour	stone grey
RAL colour	RAL 7030 - Stone grey
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

#### Dimensions

Trunking height	60 mm
Trunking width	90 mm
Measure a	135 mm

#### Installation, mounting

Base punching	Without base punching
---------------	-----------------------

#### Settings

Angle range	83 / 97 °
-------------	-----------

#### Accessories included

Accessory configuration	Moulded
-------------------------	---------

#### Equipment

Cable fixing clips included	yes
With protective film	no

## Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

## Safety

Halogen free	yes
Impact strength	IK07

## Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

## temperatur

Ambient temperature	-5...60 °C
---------------------	------------