




LFF601149010

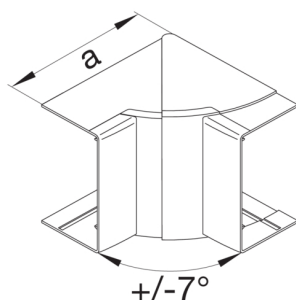

Adjus inter corner LFF60110 pure white

Technische Merkmale

Architecture

Fixing mode	Clipped
-------------	---------

Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Connectivity

Trunking coupling	without coupler
-------------------	-----------------

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	60 mm
Trunking width	110 mm
Measure a	135 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Settings

Angle range	83 / 97 °
-------------	-----------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

Cable fixing clips included	yes
With protective film	no

Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

Safety

Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...90 °C
-----------------------	------------

temperatur

Ambient temperature	-5...60 °C
---------------------	------------