


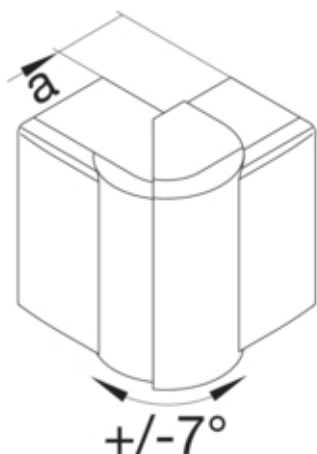

Adjus exter corner LFF60110 pure white

LFF601139010



Architecture

Fixing mode	Clipped
-------------	---------

Functions

Can be used for fire protection (keep function) According to DIN 4102-12	no
---	----

Connectivity

Trunking coupling	without coupler
-------------------	-----------------

Cover, door

Lid with softlip	No
------------------	----

Materials

RAL colour	RAL 9010 - Pure white
Colour	pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	60 mm
Trunking width	110 mm
Measure a	48 mm

Installation, mounting

Base punching	no
Protective film	No
Carpet skirting	-

Settings

Angle range	83/97 °
-------------	---------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

Overlapping	Yes
-------------	-----

Use

Product type as headline for catalogue	External corner adjustable
--	----------------------------

Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

Safety

halogen free	yes
--------------	-----

Use conditions

Ambient temperature (operation temprature)	-5/60 °C
--	----------