


M55069010

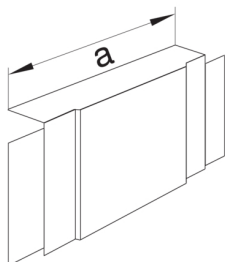

T-piece hal free LFxxx/FB 60x110mm pw

Technische Merkmale

Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Compatibility

Product compatibility	LF, FB
-----------------------	--------

Cover, door

Lid with softlip	-
------------------	---

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	61 mm
Trunking width	110 mm
Measure a	190 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------

Safety

Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...90 °C
-----------------------	------------

temperatur

Ambient temperature	-5...60 °C
---------------------	------------