




M55219010

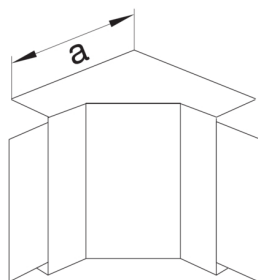

internal corner h-free LFxxx/FB 60x150pw

Technische Merkmale

Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Compatibility

Product compatibility	LF, LFF, FB
-----------------------	-------------

Connectivity

Trunking coupling	without coupler
-------------------	-----------------

Cover, door

Lid with softlip	-
------------------	---

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	61 mm
Trunking width	150 mm
Measure a	130 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Settings

Angle range	90 °
-------------	------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

Cable fixing clips included	yes
With protective film	no

Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------

Safety

Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...90 °C
-----------------------	------------

temperatur

Ambient temperature	-5...65 °C
---------------------	------------