




M55359010

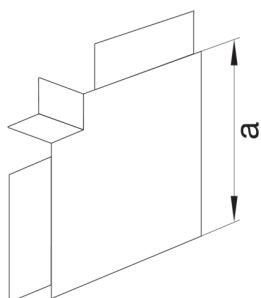

Flat corner, LF/FB 60190, pure white

Technische Merkmale

Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symetrical	yes

Compatibility

Product compatibility	LF, LFF, FB
-----------------------	-------------

Cover, door

Lid with softlip	-
------------------	---

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PVC
Type of surface treatment	untreated

Dimensions

Trunking height	61 mm
Trunking width	190 mm
Measure a	220 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Settings

Angle range	90 °
-------------	------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Safety

Halogen free	no
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...65 °C
---------------------	------------