




FB6023007030

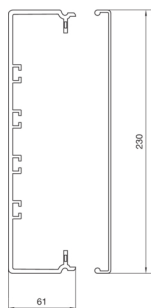

Trunking 60x230, grey

Technische Merkmale

Architecture

Fixing mode	bottom punched
-------------	----------------

Functions

Suitable for functional integrity according to DIN 4102-12	no
--	----

Configuration

Antibacterial treatment	no
Symetrical	yes

Compatibility

Device installation compatible format	Standard 60mm, CEE, MCBs
---------------------------------------	--------------------------

Connectivity

Trunking coupling	without coupler
-------------------	-----------------

Capacity

Maximum number of cables (Ø 11 mm, 50% fill)	47
Maximum number of cables (Ø 11 mm, 50% fill)	62

Cover, door

Lid mounting	External
Lid shape	loose
Lid width	230 mm
Number of lids mountable	1

Materials

Colour	stone grey
RAL colour	RAL 7030 - Stone grey
Material	PVC
Material group	plastic
Type of surface treatment	untreated
Transparent	no

Dimensions

Trunking height	61 mm
Length	2000 mm
Trunking width	230 mm

Installation, mounting

Base punching	With base punching
---------------	--------------------

Cable

Internal/useful cross section	11150 mm ²
-------------------------------	-----------------------

Scope of delivery

Delivery on roll	no
------------------	----

Equipment

Number of plugable separators	4
Compartment quantity	1 / 5
Cable retainers per meter	2
Cable fixing clips included	no
With protective film	no

Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

Safety

Protection index IP	IP30
Halogen free	no
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...65 °C
---------------------	------------