




BRP6517019010

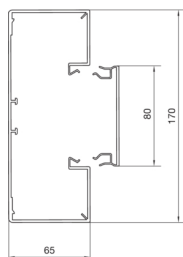

Trunking base, PVC, 65170, pure white

Technische Merkmale

Configuration

Antibacterial treatment	no
Symetrical	yes

Compatibility

Device installation compatible format	Standard 60mm, CEE, Ecoline, EIB
---------------------------------------	----------------------------------

Connectivity

Trunking coupling	Couplers as separate reference
-------------------	--------------------------------

Capacity

Maximum number of cables (Ø 11 mm, 50% fill)	38 / 57
--	---------

Cover, door

Lid mounting	Internal
Lid width	80 mm
Number of lids mountable	1

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PVC
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	65 mm
Length	2000 mm
Trunking width	170 mm

Installation, mounting

Base punching	With base punching
---------------	--------------------

Cable

Internal/useful cross section	9000 mm²
-------------------------------	----------

Equipment

Compartment quantity	1 / 2
Cable fixing clips included	no
With protective film	yes

Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------

Safety

Protection index IP	IP30
Halogen free	no
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...65 °C
---------------------	------------