



Internal corner, ATEHA, 16x30, pure white

Product Datasheet

#### Architecture

Fixing mode	Clipped
-------------	---------

#### Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

#### Configuration

Antibacterial treatment	no
Symetrical	yes

#### Connectivity

Trunking coupling	without coupler
-------------------	-----------------

#### Cover, door

Lid with softlip	No
------------------	----

#### Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	ABS
Material group	plastic
Type of surface treatment	untreated

#### Dimensions

Trunking height	16 mm
Length	49,5 mm
Trunking width	32 mm

#### Installation, mounting

Base punching	Without base punching
---------------	-----------------------

#### Settings

Angle range	83 / 140 °
-------------	------------


#### Accessories included

Accessory configuration	Moulded
-------------------------	---------

#### Equipment

Cable fixing clips included	no
With protective film	no

ATA163049010

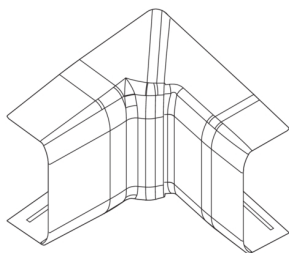

## Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

## Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

## Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

## temperatur

Ambient temperature	-5...60 °C
---------------------	------------