


Internal corner VDI SL20055 aok

SL200554D5

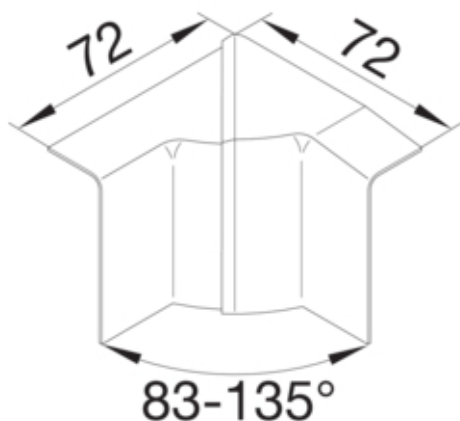

Architecture

Fixing mode	Clamping
-------------	----------

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	oak
Material	ABS
Material group	plastic
Type of surface treatment	Tampography

Dimensions

Trunking height	55 mm
Trunking width	20 mm

Installation, mounting

Protective film	No
Carpet skirting	-

Settings

Angle range	83/135 °
-------------	----------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

Overlapping	Yes
-------------	-----

Use

Product type as headline for catalogue	Internal corner adjustable
--	----------------------------

Standards

Approvals	CE
European directive RoHs	voluntary compliance

Safety

halogen free	yes
--------------	-----

Use conditions

Ambient temperature (operation temprature)	-5/65 °C
--	----------