



## internal corner LFH 40060, pure white

Product Datasheet

### Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

### Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

### Configuration

Antibacterial treatment	no
Symmetrical	yes

### Connectivity

Trunking coupling	without coupler
-------------------	-----------------

### Cover, door

Lid with softlip	-
------------------	---

### Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

### Dimensions

Trunking height	40 mm
Trunking width	60 mm
Measure a	85 mm

### Installation, mounting

Base punching	Without base punching
---------------	-----------------------

### Settings

Angle range	90 °
-------------	------

### Accessories included

Accessory configuration	Moulded
-------------------------	---------


### Equipment

Cable fixing clips included	yes
With protective film	no

### Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------

M66619010

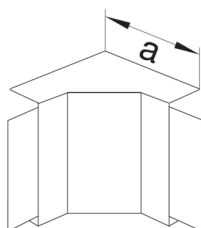

**Safety**

Halogen free	yes
Impact strength	IK07

**Use conditions**

Operating temperature	-5...90 °C
-----------------------	------------

**temperatur**

Ambient temperature	-30...90 °C
---------------------	-------------