



T-piece, LFH 40060, pure white

Product Datasheet

Architecture

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

Functions

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Cover, door

Lid with softlip	-
------------------	---

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	40 mm
Trunking width	60 mm
Measure a	170 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Standards

European directive RoHs	voluntary compliance
-------------------------	----------------------


Safety

Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...90 °C
-----------------------	------------

M66669010

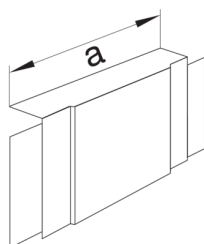

temperatur

Ambient temperature	-30...90 °C
---------------------	-------------