



**external corner LFH 60090, pure white**

Product Datasheet

**Architecture**

Fixing mode	Hold in position thanks to lid
-------------	--------------------------------

**Functions**

Overlapping	no
Suitable for functional integrity according to DIN 4102-12	no

**Configuration**

Antibacterial treatment	no
Symetrical	yes

**Connectivity**

Trunking coupling	without coupler
-------------------	-----------------

**Cover, door**

Lid with softlip	-
------------------	---

**Materials**

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	PC-ABS
Material group	plastic
Type of surface treatment	untreated

**Dimensions**

Trunking height	60 mm
Trunking width	90 mm
Measure a	70 mm

**Installation, mounting**

Base punching	Without base punching
---------------	-----------------------

**Settings**

Angle range	90 °
-------------	------

**Accessories included**

Accessory configuration	Moulded
-------------------------	---------


**Equipment**

With protective film	no
----------------------	----

**Standards**

European directive RoHs	voluntary compliance
-------------------------	----------------------

M66729010

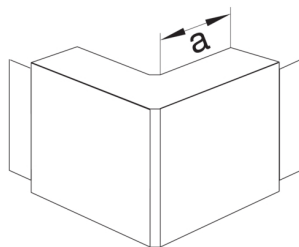

## Safety

Halogen free	yes
Impact strength	IK07

## Use conditions

Operating temperature	-5...90 °C
-----------------------	------------

## temperatur

Ambient temperature	-30...90 °C
---------------------	-------------