


VZ605N1

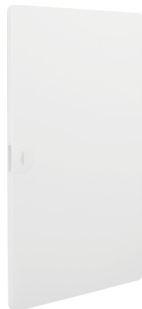

VZ605N

Door, golf, white, VF/VS312

Technische Merkmale

Architecture

Intended door position	left
Fixing mode	Clamping

Configuration

Version as door for disconnecting switch interlocking	no
---	----

Cover, door

Type of door closing	Latch
Door type for switch gear cabinet	Stop door
Door leave	single
Door quantity	1
With cut out	yes
Door included	yes
Transparent cover or door	no

Materials

Colour	RAL 9010
Colour	white
RAL colour	RAL 9010 - Pure white
Material	plastic
Surface appearance	glossy
Type of surface treatment	untreated

Dimensions

Depth of installed product	16,5 mm
Internal depth	16,5 mm
Height of installed product	500 mm
Width of installed product	280 mm
Built-in height	500 mm
Built-in width	280 mm

Installation, mounting

Suitable for outdoor use	no
--------------------------	----

Equipment

Number of rows	3
Quantity of section in width	1

Standards

European directive WEEE	not concerned
-------------------------	---------------

Safety

IK protection code against mechanical impacts	IK07
Protection index IP	IP40
Protection class	isol.class II
Halogen free	yes
Ultraviolet resistant	no

Use conditions

Operating temperature	-25...40 °C
-----------------------	-------------

Shape

Slotted	no
---------	----