



External corner, ATEHA, 16x30, pure white

Product Datasheet

Architecture

Fixing mode	Clipped
-------------	---------

Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symetrical	yes

Connectivity

Trunking coupling	without coupler
-------------------	-----------------

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	16 mm
Length	26,5 mm
Trunking width	32 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Settings

Angle range	83 / 140 °
-------------	------------

Accessories included

Accessory configuration	Moulded
-------------------------	---------


Equipment

With protective film	no
----------------------	----

Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

ATA163039010

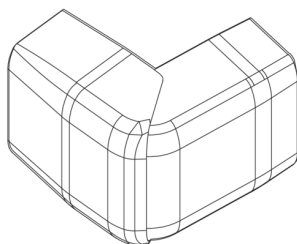

Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...60 °C
---------------------	------------