




ATA205059010

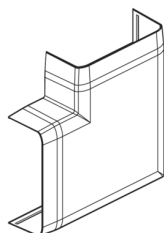

Flat corner, ATEHA, 20x50, pure white

Product Datasheet

Architecture

Fixing mode	Clipped
-------------	---------

Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	ABS
Type of surface treatment	untreated

Dimensions

Trunking height	20 mm
Length	78 mm
Trunking width	52 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Settings

Angle range	90 °
-------------	------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Standards

Approvals	EN50085-2-1
-----------	-------------

Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...60 °C
---------------------	------------