




ATA123059010

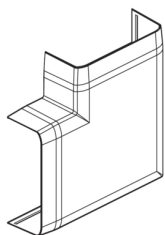

Flat corner, ATEHA, 12x30, pure white

Product Datasheet

Architecture

| | |
|-------------|---------|
| Fixing mode | Clipped |
|-------------|---------|

Functions

| | |
|------------------------------------------------------------|-----|
| Overlapping | yes |
| Suitable for functional integrity according to DIN 4102-12 | no |

Configuration

| | |
|-------------------------|-----|
| Antibacterial treatment | no |
| Symmetrical | yes |

Cover, door

| | |
|------------------|----|
| Lid with softlip | No |
|------------------|----|

Materials

| | |
|---------------------------|-----------------------|
| Colour | pure white |
| RAL colour | RAL 9010 - Pure white |
| Material | ABS |
| Type of surface treatment | untreated |

Dimensions

| | |
|-----------------|-------|
| Trunking height | 13 mm |
| Length | 58 mm |
| Trunking width | 32 mm |

Installation, mounting

| | |
|---------------|-----------------------|
| Base punching | Without base punching |
|---------------|-----------------------|

Settings

| | |
|-------------|------|
| Angle range | 90 ° |
|-------------|------|

Accessories included

| | |
|-------------------------|---------|
| Accessory configuration | Moulded |
|-------------------------|---------|

Equipment

| | |
|----------------------|----|
| With protective film | no |
|----------------------|----|

Standards

| | |
|-----------|-------------|
| Approvals | EN50085-2-1 |
|-----------|-------------|

Safety

| | |
|---------------------|------|
| Protection index IP | IP40 |
| Halogen free | yes |
| Impact strength | IK07 |

Use conditions

| | |
|-----------------------|------------|
| Operating temperature | -5...60 °C |
|-----------------------|------------|

temperatur

| | |
|---------------------|------------|
| Ambient temperature | -5...60 °C |
|---------------------|------------|