




ATA123069010

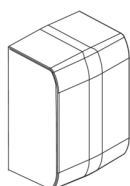

End cap, ATEHA, 12x30, pure white

Product Datasheet

Architecture

Fixing mode Clipped

Functions

Overlapping yes

Suitable for functional integrity according to DIN 4102-12 no

Configuration

Antibacterial treatment no

Connectivity

Trunking coupling without coupler

Materials

Colour pure white

RAL colour RAL 9010 - Pure white

Material ABS

Material group plastic

Type of surface treatment untreated

Dimensions

Trunking height 13 mm

Trunking width 32 mm

Equipment

With protective film no

Standards

Approvals EN50085-2-1

European directive RoHs voluntary compliance

Safety

Protection index IP IP40

Halogen free yes

Impact strength IK07

Use conditions

Operating temperature -5...60 °C

temperatur

Ambient temperature -5...60 °C