




ATA207559010

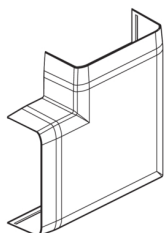

## Flat corner, ATEHA, 20x75, pure white

### Product Datasheet

#### Architecture

Fixing mode	Clipped
-------------	---------

#### Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

#### Configuration

Antibacterial treatment	no
Symmetrical	yes

#### Cover, door

Lid with softlip	No
------------------	----

#### Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	ABS
Type of surface treatment	untreated

#### Dimensions

Trunking height	20 mm
Length	100 mm
Trunking width	74 mm

#### Installation, mounting

Base punching	Without base punching
---------------	-----------------------

#### Settings

Angle range	90 °
-------------	------

#### Accessories included

Accessory configuration	Moulded
-------------------------	---------

#### Equipment

With protective film	no
----------------------	----

#### Standards

Approvals	EN50085-2-1
-----------	-------------

#### Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

**Use conditions**

Operating temperature	-5...60 °C
-----------------------	------------

**temperatur**

Ambient temperature	-5...60 °C
---------------------	------------