




ATA207589010

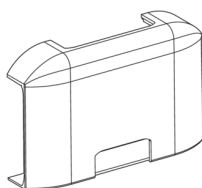

T piece, ATEHA, 20x75, pure white

Product Datasheet

Architecture

Fixing mode	Clipped
-------------	---------

Functions

Overlapping	yes
Suitable for functional integrity according to DIN 4102-12	no

Configuration

Antibacterial treatment	no
Symmetrical	yes

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	ABS
Material group	plastic
Type of surface treatment	untreated

Dimensions

Trunking height	20 mm
Trunking width	74 mm
Width	20 mm

Installation, mounting

Base punching	Without base punching
---------------	-----------------------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Standards

Approvals	EN50085-2-1
European directive RoHs	voluntary compliance

Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	-5...60 °C
-----------------------	------------

temperatur

Ambient temperature	-5...60 °C
---------------------	------------