


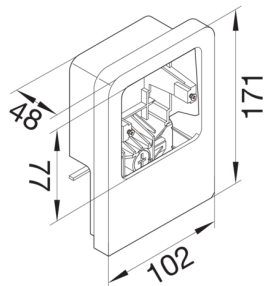

SL200559119010



**acc.box univ. SL20055 purewhite**

Product Datasheet

**Architecture**

Fixing mode	Clamping and screwable
-------------	------------------------

**Configuration**

Antibacterial treatment	no
Empty housing	no

**Compatibility**

Device installation compatible format	Standard 60mm
---------------------------------------	---------------

**Materials**

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	plastic
Material group	mixed material

**Dimensions**

Depth of installed product	48 mm
Height of installed product	145 mm
Trunking height	55 mm
Length	102 mm
Trunking width	20 mm
Format	overhanging wiring accessory

**Installation, mounting**

Mounting way	horizontal
--------------	------------

**Accessories included**

Fitted with	empty
-------------	-------

**Equipment**

Number of units	1
-----------------	---

**Standards**

Approvals	CE
European directive RoHs	voluntary compliance

**Safety**

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

**Use conditions**

Operating temperature	5...60 °C
-----------------------	-----------

**temperatur**

Ambient temperature

5...60 °C