


SL20055911D1

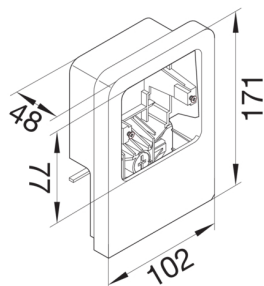

acc.box univ. SL20055 alu

Product Datasheet

Architecture

Fixing mode	Clamping and screwable
-------------	------------------------

Configuration

Antibacterial treatment	no
Empty housing	no

Compatibility

Device installation compatible format	Standard 60mm
---------------------------------------	---------------

Materials

Colour	aluminium
Colour	aluminium optics
Material	plastic
Material group	mixed material
Type of surface treatment	Painted

Dimensions

Depth of installed product	48 mm
Height of installed product	145 mm
Trunking height	55 mm
Length	102 mm
Trunking width	20 mm
Format	overhanging wiring accessory

Installation, mounting

Mounting way	horizontal
--------------	------------

Accessories included

Fitted with	empty
-------------	-------

Equipment

Number of units	1
-----------------	---

Standards

Approvals	CE
European directive RoHs	voluntary compliance

Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	5...60 °C
-----------------------	-----------

temperatur

Ambient temperature	5...60 °C
---------------------	-----------