




SL200554D4

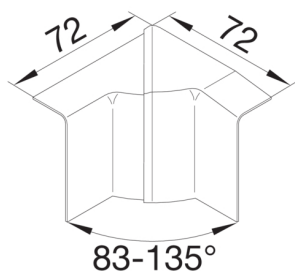

Internal corner VDI SL20055 cherry

Product Datasheet

Architecture

Fixing mode	Clamping
-------------	----------

Functions

Overlapping	yes
-------------	-----

Configuration

Symmetrical	yes
-------------	-----

Cover, door

Lid with softlip	No
------------------	----

Materials

Colour	cherry
Material	ABS
Material group	plastic
Type of surface treatment	Tampography

Dimensions

Trunking height	55 mm
Trunking width	20 mm

Settings

Angle range	83 / 135 °
-------------	------------

Accessories included

Accessory configuration	Moulded
-------------------------	---------

Equipment

With protective film	no
----------------------	----

Standards

Approvals	CE
European directive RoHs	voluntary compliance

Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

Use conditions

Operating temperature	5...60 °C
-----------------------	-----------

temperatur

Ambient temperature	5...60 °C
---------------------	-----------