




SL200809119010

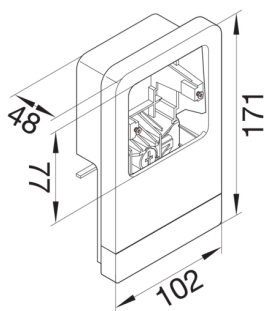

## acc.box univ. SL20080 purewhite

### Product Datasheet

#### Architecture

Fixing mode	Clamping and screwable
-------------	------------------------

#### Configuration

Antibacterial treatment	no
Empty housing	no

#### Compatibility

Device installation compatible format	Standard 60mm
---------------------------------------	---------------

#### Materials

Colour	pure white
RAL colour	RAL 9010 - Pure white
Material	plastic
Material group	mixed material

#### Dimensions

Depth of installed product	48 mm
Height of installed product	171 mm
Trunking height	80 mm
Length	102 mm
Trunking width	20 mm
Format	overhanging wiring accessory

#### Installation, mounting

Mounting way	horizontal
--------------	------------

#### Accessories included

Fitted with	empty
-------------	-------

#### Equipment

Number of units	1
-----------------	---

#### Standards

Approvals	CE
European directive RoHs	voluntary compliance

#### Safety

Protection index IP	IP40
Halogen free	yes
Impact strength	IK07

#### Use conditions

Operating temperature	5...60 °C
-----------------------	-----------

**temperatur**

Ambient temperature

5...60 °C